




Interchangeable inch round air cylinder DPRA

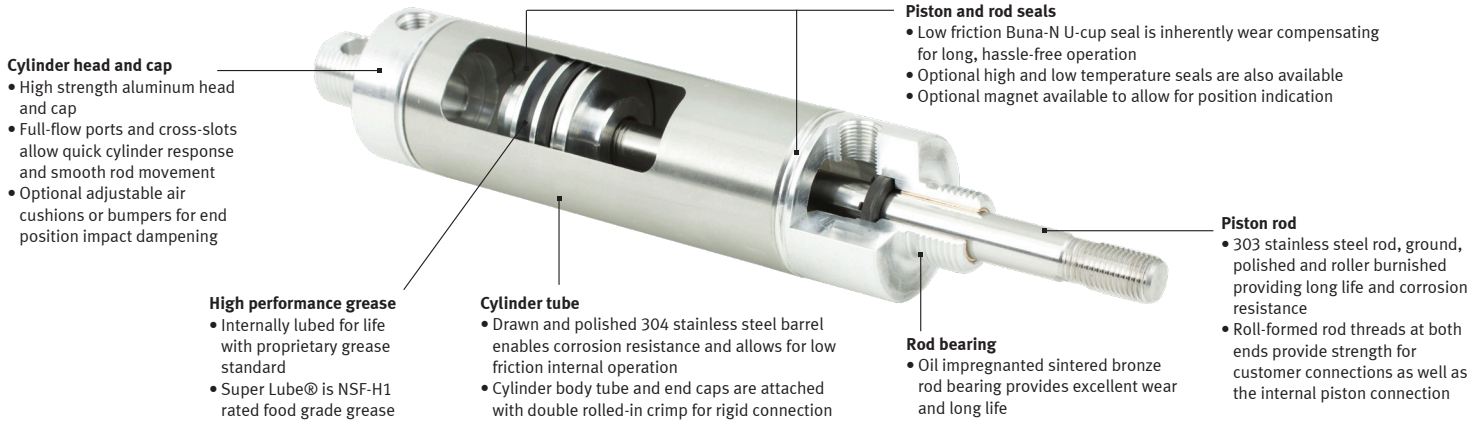

Common configurations in stock and available now.

Nose mount, axial port	Stroke length [inches]	Piston diameter									
		3/4"		1 1/16"		1 1/4"		1 1/2"		2"	
	1/2"	8217823 ★	DPRA-N-3/4"-0.5-NGP4-N	8217854 ★	DPRA-N-11/16"-0.5-NGP4-N						
	1"	8217824 ★	DPRA-N-3/4"-1-NGP4-N	8217838 ★	DPRA-N-1 1/16"-1-NGP4-N	8217855 ★	DPRA-N-1 1/4"-1-NGP4-N	8217879 ★	DPRA-N-1 1/2"-1-NGP4-N	8217891 ★	DPRA-N-2"-1-NGP4-N
	1 1/2"	8217826 ★	DPRA-N-3/4"-1.5-NGP4-N	8217853 ★	DPRA-N-1 1/16"-1.5-NGP4-N			8217866 ★	DPRA-N-1 1/2"-1.5-NGP4-N		
	2"	8217827 ★	DPRA-N-3/4"-2-NGP4-N	8217845 ★	DPRA-N-1 1/16"-2-NGP4-N	8217856 ★	DPRA-N-1 1/4"-2-NGP4-N	8217867 ★	DPRA-N-1 1/2"-2-NGP4-N	8217880 ★	DPRA-N-2"-2-NGP4-N
	3"	8217828 ★	DPRA-N-3/4"-3-NGP4-N	8217846 ★	DPRA-N-1 1/16"-3-NGP4-N	8217857 ★	DPRA-N-1 1/4"-3-NGP4-N	8217868 ★	DPRA-N-1 1/2"-3-NGP4-N	8217881 ★	DPRA-N-2"-3-NGP4-N
	4"	8217829 ★	DPRA-N-3/4"-4-NGP4-N	8217842 ★	DPRA-N-1 1/16"-4-NGP4-N	8217858 ★	DPRA-N-1 1/4"-4-NGP4-N	8217869 ★	DPRA-N-1 1/2"-4-NGP4-N	8217882 ★	DPRA-N-2"-4-NGP4-N
	5"			8217844 ★	DPRA-N-1 1/16"-5-NGP4-N	8217859 ★	DPRA-N-1 1/4"-5-NGP4-N	8217870 ★	DPRA-N-1 1/2"-5-NGP4-N	8217883 ★	DPRA-N-2"-5-NGP4-N
6"							8217871 ★	DPRA-N-1 1/2"-6-NGP4-N	8217884 ★	DPRA-N-2"-6-NGP4-N	

Rear pivot	Stroke length [inches]	Piston diameter									
		3/4"		1 1/16"		1 1/4"		1 1/2"		2"	
	1/2"	8217830 ★	DPRA-N-3/4"-0.5-ME-N	8217839 ★	DPRA-N-1 1/16"-0.5-ME-N						
	1"	8217825 ★	DPRA-N-3/4"-1-ME-N	8217840 ★	DPRA-N-1 1/16"-1-ME-N	8217860 ★	DPRA-N-1 1/4"-1-U-N	8217872 ★	DPRA-N-1 1/2"-1-ME-N	8217885 ★	DPRA-N-2"-1-UB-N
	1 1/2"	8217831 ★	DPRA-N-3/4"-1.5-ME-N	8217849 ★	DPRA-N-1 1/16"-1.5-ME-N			8217873 ★	DPRA-N-1 1/2"-1.5-ME-N		
	2"	8217832 ★	DPRA-N-3/4"-2-ME-N	8217847 ★	DPRA-N-1 1/16"-2-ME-N	8217865 ★	DPRA-N-1 1/4"-2-U-N	8217874 ★	DPRA-N-1 1/2"-2-ME-N	8217886 ★	DPRA-N-2"-2-UB-N
	3"	8217833 ★	DPRA-N-3/4"-3-ME-N	8217848 ★	DPRA-N-1 1/16"-3-ME-N	8217861 ★	DPRA-N-1 1/4"-3-U-N	8217875 ★	DPRA-N-1 1/2"-3-ME-N	8217887 ★	DPRA-N-2"-3-UB-N
	4"	8217834 ★	DPRA-N-3/4"-4-ME-N	8217843 ★	DPRA-N-1 1/16"-4-ME-N	8217862 ★	DPRA-N-1 1/4"-4-U-N	8217876 ★	DPRA-N-1 1/2"-4-ME-N	8217888 ★	DPRA-N-2"-4-UB-N
	5"	8217835 ★	DPRA-N-3/4"-5-ME-N	8217850 ★	DPRA-N-1 1/16"-5-ME-N	8217863 ★	DPRA-N-1 1/4"-5-U-N	8217877 ★	DPRA-N-1 1/2"-5-ME-N	8217889 ★	DPRA-N-2"-5-UB-N
6"			8217852 ★	DPRA-N-1 1/16"-6-ME-N	8217864 ★	DPRA-N-1 1/4"-6-U-N	8217878 ★	c DPRA-N-1 1/2"-6-ME-N	8217890 ★	DPRA-N-2"-6-UB-N	

Single acting, spring return		Piston diameter			
		3/4"		1 1/16"	
Nose mount	1"	8217836 ★	DPRA-N-3/4"-1-SNGP4-N	8217851 ★	DPRA-N-1 1/16"-1-SNGP4-N
Rear pivot	1"	8217837 ★	DPRA-N-3/4"-1-SME-N	8217841 ★	DPRA-N-1 1/16"-1-SME-N

Please refer to the online catalog → www.festo.com/catalog/dpra

